

The New Standard for Powerful Charging



Smart, reliable charging from the brand you trust.

The Type A and Type-C™ USB Charger/Tamper-Resistant Receptacle offers superior charging power for smartphones, tablets, laptops, monitors, printers and more. Two high powered vertical USB Ports, one Type A and one Type-C, deliver a combined total of 5.1A charging current and 25+ watts of power. A smart chip recognizes and optimizes the charging requirements of individual devices and the Type-C port enables the cables to be inserted easily in either direction.

Applications

Ideal for residential and commercial applications including kitchens, bedrooms, home offices, college dormitories, airport lounges, hospitals, salons and spas, hotels, meeting rooms, cafes, restaurants and more.

The Type A and Type-C™ USB Charger/Tamper-Resistant Receptacle is a powerful solution to help keep your devices charged with ease and style.




Features

- Smart chip recognizes and optimizes the charging requirements of individual devices
- Type A and Type-C ports charge phones and tablets faster than manufacturer supplied AC adapters
- The Type-C Port provides up to 59% faster charging power versus competitors*
- One Type A Port and one Type-C Port; combined total of 5.1A of charging power
 - Type-C Port can charge maximum 3 Amps @ 5V
 - Type A Port can charge maximum 2.4 Amps @ 5V
- Tamper-Resistant to help prevent access by most non-rated/foreign objects
- USB Ports tested to withstand over 10,000 insertions
- Charges most Type A and Type-C USB powered devices
- Spec Grade



Type-C devices have a Reversible Connector
 USB-C is a new user-friendly reversible connector that allows you to plug in your cable in any direction.

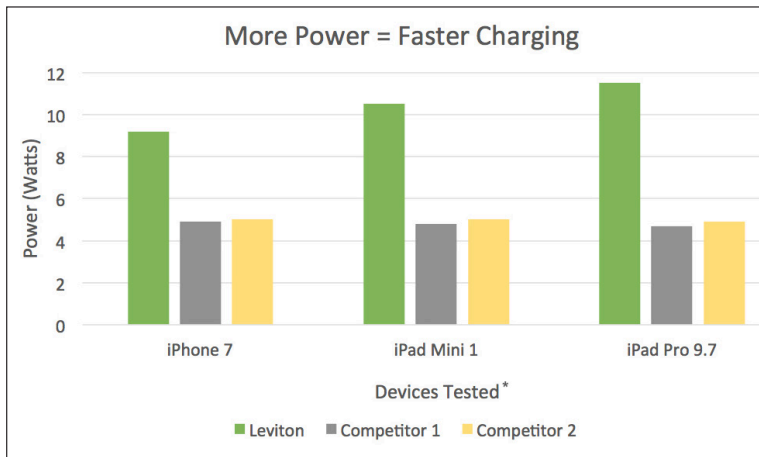

*Testing performed using Lightning cable on C Port with iPhone 7, iPad Mini 1, iPad Pro 9.7

- Type-C Port provides more power for faster charging
- Hospital Grade models available with brass self-grounding clip to ensure secure and reliable performance
- Compatible with Decora® wallplates and Decora Plus™ screwless wallplates

Typical Specifications

- Operating Temperature Range: -10°C to 40°C


Agency Standards and Compliance

- cCSAus Listed

Warranty Information

- Five-Year Limited Warranty

Dimensional Drawings

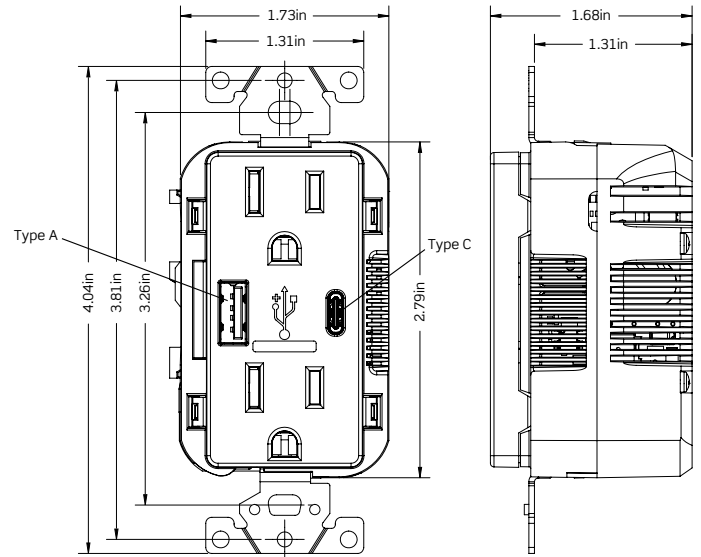

Ordering Information

Cat. No.	Description	Combined Charging Capability	Rating	Color
T5633	15A Type A and Type-C USB Charger Tamper-Resistant Receptacle	5.1A	15A – 125V	W, I, T, GY, E, B
T5633-HG	15A Type A and Type-C USB Charger Tamper-Resistant Hospital Grade Receptacle	5.1A	15A – 125V	W, I, T, GY, E, R, -
T5833	20A Type A and Type-C USB Charger Tamper-Resistant Receptacle	5.1A	20A – 125V	W, I, T, GY, E, B

To order colors, add suffix to Cat. No.: White (-W), Ivory (-I), Light Almond (-T), Gray (-GY), Black (-E), Brown (-B), Red (-R). (-) Designates brown for Hospital Grade devices (no suffix).

Use of third party trademarks herein are for informational purposes only and does not indicate affiliation, sponsorship or endorsement. Apple, iPad, iPhone, Samsung, Nexus and Pixel are trademarks of their respective owners.



Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747-3138
 Telephone: 1-800-323-8920 • FAX: 1-800-832-9538
 Tech Line: 1-800-824-3005
 Mon-Fri 8am-10pm EST, Saturday 9am-7pm EST

Visit our Website at: www.leviton.com/us

© 2018 Leviton Manufacturing Co., Inc. All rights reserved.

