



Wetguard®

# Watertight Wiring Devices

PARTNER PLAYBOOK

A complete collection of watertight devices for demanding industrial environments





# WETGUARD® WATERTIGHT WIRING DEVICES



FDBX2-Y

CAT #	COLOR	DESCRIPTION
<b>Non-Metallic FD Boxes</b>		
FDBX1-Y	Yellow	Single-Gang FD Box
FDBX1-GY	Gray	Single-Gang FD Box
FDBX2-Y	Yellow	2-Gang FD Box
FDBX2-GY	Gray	2-Gang FD Box
FDBX3-Y	Yellow	3-Gang FD Box
FDBX3-GY	Gray	3-Gang FD Box
<b>Stainless Steel FD Boxes</b>		
FDSS1	Stainless Steel	Single-Gang FD Box
FDSS2	Stainless Steel	2-Gang FD Box
<b>Covers</b>		
COVER-S	Yellow	Single Gang Switch Cover and Gasket for 15 Amp - 40 Amp Toggle Switches, Including Leviton Manual Motor Starters
COVER-GS	Gray	Single Gang Switch Cover and Gasket for 15 Amp - 40 Amp Toggle Switches, Including Leviton Manual Motor Starters
WTCVD	Yellow	Wetguard Replacement Cover and Gasket for Wetguard Duplex Outlets Only
WTCVS-15	Yellow	Wetguard Replacement Cover and Gasket for 15 Amp and 20 Amp Straight and 15 Amp Locking Single Inlets and Outlets
WTCVS-20	Yellow	Wetguard Replacement Cover and Gasket for all 20 Amp Locking Single Inlets and Outlets
WTCVS-30	Yellow	Wetguard Replacement Cover and Gasket for all 30 Amp Locking Single Inlets and Outlets
WP459	Yellow	Wetguard Blank Plate and Gasket
60W03	Yellow	Wetguard Replacement Cover and Gasket for 15 Amp and 20 Amp Straight Blade and 15 Amp Locking Box Mount Single Flush Receptacles
60W04	Yellow	Wetguard Replacement Cover and Gasket for 20 Amp Locking Box Mount Single Flush Receptacles
60W05	Yellow	Wetguard Replacement Cover and Gasket for 30 Amp Locking Box Mount Single Flush Receptacles
60W03-B	Black	Wetguard Replacement Cover and Gasket for 15 Amp and 20 Amp Straight Blade and 15 Amp Locking Box Mount Single Flush Receptacles
60W04-B	Black	Wetguard Replacement Cover and Gasket for 20 Amp Locking Box Mount Single Flush Receptacles
60W05-B	Black	Wetguard Replacement Cover and Gasket for 30 Amp Locking Box Mount Single Flush Receptacles



FDSS1




WP459



WTCVD



COVER-GS

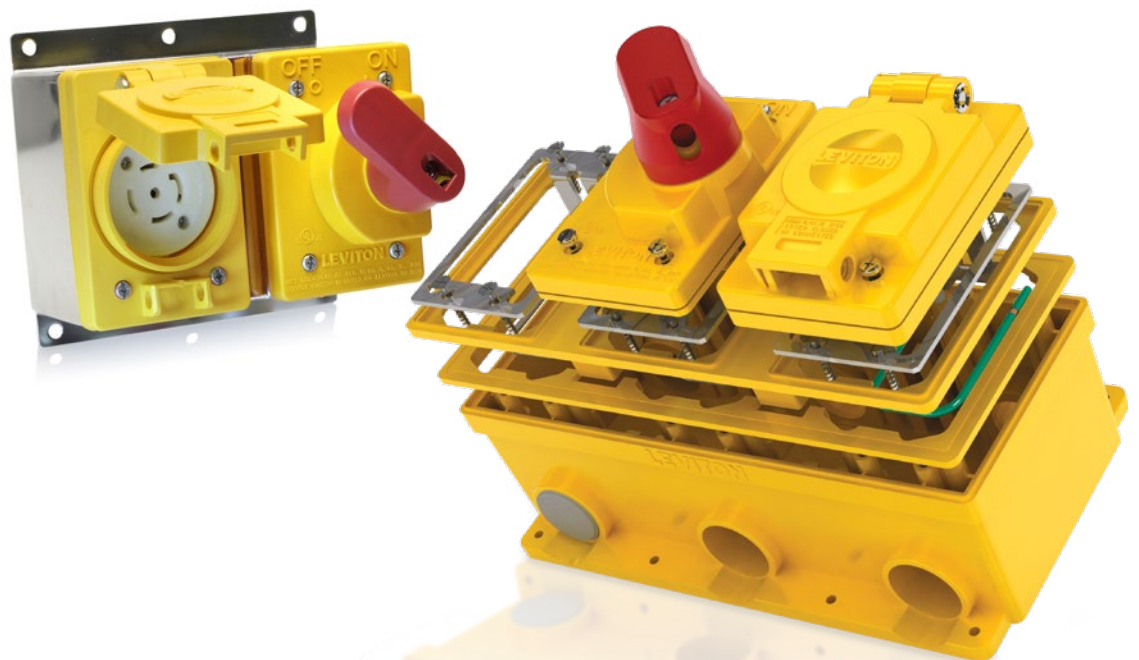

CAT #	COLOR	DESCRIPTION		
<b>15 Amp Straight Blade &amp; Locking Devices</b>				
14W04	Yellow	15A, 125V, 2P, 2W, Straight Blade Plug	IP69K	
15W04	Yellow	15A, 125V, 2P, 2W, Straight Blade Connector		
90W04-S	Yellow	15A, 125V, 2P, 2W, Straight Blade Single Outlet		
80W04-D	Yellow	15A, 125V, 2P, 2W, Straight Blade Duplex Outlet		
59W04	Yellow	15A, 125V, 2P, 2W, Straight Blade Single Inlet		
79W04-C	Yellow	15A, 125V, 2P, 2W, Straight Blade Connector for Single Inlet		
24W04	Yellow	15A, 125V, 2P, 2W, Locking Plug	IP69K	
25W04	Yellow	15A, 125V, 2P, 2W, Locking Connector		
95W04-S	Yellow	15A, 125V, 2P, 2W, Locking Single Outlet		
85W04-D	Yellow	15A, 125V, 2P, 2W, Locking Duplex Outlet		
64W04	Yellow	15A, 125V, 2P, 2W, Locking Single Inlet		
74W04-C	Yellow	15A, 125V, 2P, 2W, Locking Connector for Single Inlet		
14W47*	Yellow	15A, 125V, 2P, 3W, Straight Blade Plug	IP69K	
14W47-B	Black	15A, 125V, 2P, 3W, Straight Blade Plug		
15W47*	Yellow	15A, 125V, 2P, 3W, Straight Blade Connector		
15W47-B	Black	15A, 125V, 2P, 3W, Straight Blade Connector		
90W47-S	Yellow	15A, 125V, 2P, 3W, Straight Blade Single Outlet		
80W47-D	Yellow	15A, 125V, 2P, 3W, Straight Blade Duplex Outlet		
59W47	Yellow	15A, 125V, 2P, 3W, Straight Blade Single Inlet		
79W47-C	Yellow	15A, 125V, 2P, 3W, Straight Blade Connector for Single Inlet		
14W49	Yellow	15A, 250V, 2P, 3W, Straight Blade Plug		IP69K
15W49	Yellow	15A, 250V, 2P, 3W, Straight Blade Connector		
90W49-S	Yellow	15A, 250V, 2P, 3W, Straight Blade Single Outlet		
80W49-D	Yellow	15A, 250V, 2P, 3W, Straight Blade Duplex Outlet		
59W49	Yellow	15A, 250V, 2P, 3W, Straight Blade Single Inlet		
79W49-C	Yellow	15A, 250V, 2P, 3W, Straight Blade Connector for Single Inlet		
14W34	Yellow	15A, 277V, 2P, 3W, Straight Blade Plug	IP69K	
15W34	Yellow	15A, 277V, 2P, 3W, Straight Blade Connector		
14W15	Yellow	15A, 347V, 2P, 3W, Straight Blade Plug	IP69K	
15W16	Yellow	15A, 347V, 2P, 3W, Straight Blade Connector		
24W47*	Yellow	15A, 125V, 2P, 3W, Locking Plug	IP69K	
24W47-B	Black	15A, 125V, 2P, 3W, Locking Plug		
25W47*	Yellow	15A, 125V, 2P, 3W, Locking Connector		
25W47-B	Black	15A, 125V, 2P, 3W, Locking Connector		
95W47-S	Yellow	15A, 125V, 2P, 3W, Locking Single Outlet		
85W47-D	Yellow	15A, 125V, 2P, 3W, Locking Duplex Outlet		
64W47	Yellow	15A, 125V, 2P, 3W, Locking Single Inlet		
74W47-C	Yellow	15A, 125V, 2P, 3W, Locking Connector for Single Inlet		
24W49	Yellow	15A, 250V, 2P, 3W, Locking Plug	IP69K	
25W49	Yellow	15A, 250V, 2P, 3W, Locking Connector		
95W49-S	Yellow	15A, 250V, 2P, 3W, Locking Single Outlet		
85W49-D	Yellow	15A, 250V, 2P, 3W, Locking Duplex Outlet		
64W49	Yellow	15A, 250V, 2P, 3W, Locking Single Inlet		
74W49-C	Yellow	15A, 250V, 2P, 3W, Locking Connector for Single Inlet		
24W34	Yellow	15A, 277V, 2P, 3W, Locking Plug	IP69K	
25W34	Yellow	15A, 277V, 2P, 3W, Locking Connector		
95W34-S	Yellow	15A, 277V, 2P, 3W, Locking Single Outlet		
85W34-D	Yellow	15A, 277V, 2P, 3W, Locking Duplex Outlet		
64W34	Yellow	15A, 277V, 2P, 3W, Locking Single Inlet		
74W34-C	Yellow	15A, 277V, 2P, 3W, Locking Connector for Single Inlet		



14W04



90W04



24W47-IN



24W04



79W04-C

\* Replacement interior available. To order, add "-IN" to catalog number (Ex: 14W47-IN).

‡ Wetguard plugs & connectors are IP69K rated when caps are attached (Listed on page 7).

# WETGUARD® WATERTIGHT WIRING DEVICES



24W07



80W07-D



25W47-B



76W76-C



90W47

CAT #	COLOR	DESCRIPTION	
<b>15 &amp; 20 Amp Straight Blade &amp; Locking Devices</b>			
14W07	Yellow	15A, 125V, 3P, 3W, Straight Blade Plug	IP69K
15W07	Yellow	15A, 125V, 3P, 3W, Straight Blade Connector	
90W07-S	Yellow	15A, 125V, 3P, 3W, Straight Blade Single Outlet	
80W07-D	Yellow	15A, 125V, 3P, 3W, Straight Blade Duplex Outlet	
59W07	Yellow	15A, 125V, 3P, 3W, Straight Blade Single Inlet	
79W07-C	Yellow	15A, 125V, 3P, 3W, Straight Blade Connector for Single Inlet	
24W07	Yellow	15A, 125V, 3P, 3W, Locking Plug	IP69K
25W07	Yellow	15A, 125V, 3P, 3W, Locking Connector	
95W07-S	Yellow	15A, 125V, 3P, 3W, Locking Single Outlet	
85W07-D	Yellow	15A, 125V, 3P, 3W, Locking Duplex Outlet	
64W07	Yellow	15A, 125V, 3P, 3W, Locking Single Inlet	
74W07-C	Yellow	15A, 125V, 3P, 3W, Locking Connector for Single Inlet	
26W07	Yellow	20A, 250V, 2P, 2W, Locking Plug	IP69K
27W07	Yellow	20A, 250V, 2P, 2W, Locking Connector	
97W07-S	Yellow	20A, 250V, 2P, 2W, Locking Single Outlet	
87W07-D	Yellow	20A, 250V, 2P, 2W, Locking Duplex Outlet	
66W07	Yellow	20A, 250V, 2P, 2W, Locking Single Inlet	
76W07-C	Yellow	20A, 250V, 2P, 2W, Locking Connector for Single Inlet	
14W33	Yellow	20A, 125V, 2P, 3W, Straight Blade Plug	IP69K
15W33	Yellow	20A, 125V, 2P, 3W, Straight Blade Connector	
90W33-S	Yellow	20A, 125V, 2P, 3W, Straight Blade Single Outlet	
59W33	Yellow	20A, 125V, 2P, 3W, Straight Blade Single Inlet	
79W33-C	Yellow	20A, 125V, 2P, 3W, Straight Blade Connector for Single Inlet	
14W48	Yellow	20A, 250V, 2P, 3W, Straight Blade Plug	IP69K
15W48	Yellow	20A, 250V, 2P, 3W, Straight Blade Connector	
90W48-S	Yellow	20A, 250V, 2P, 3W, Straight Blade Single Outlet	
59W48	Yellow	20A, 250V, 2P, 3W, Straight Blade Single Inlet	
79W48-C	Yellow	20A, 250V, 2P, 3W, Straight Blade Connector for Single Inlet	
14W17	Yellow	20A, 347V, 2P, 3W, Straight Blade Plug	IP69K
15W18	Yellow	20A, 347V, 2P, 3W, Straight Blade Connector	
<b>20 Amp Locking Devices</b>			
26W47*	Yellow	20A, 125V, 2P, 3W, Locking Plug	IP69K
26W47-B	Black	20A, 125V, 2P, 3W, Locking Plug	
27W47*	Yellow	20A, 125V, 2P, 3W, Locking Connector	
27W47-B	Black	20A, 125V, 2P, 3W, Locking Connector	
97W47-S	Yellow	20A, 125V, 2P, 3W, Locking Single Outlet	
66W47	Yellow	20A, 125V, 2P, 3W, Locking Single Inlet	
76W47-C	Yellow	20A, 125V, 2P, 3W, Locking Connector for Single Inlet	
26W48	Yellow	20A, 250V, 2P, 3W, Locking Plug	IP69K
26W48-B	Black	20A, 250V, 2P, 3W, Locking Plug	
27W48	Yellow	20A, 250V, 2P, 3W, Locking Connector	
27W48-B	Black	20A, 250V, 2P, 3W, Locking Connector	
97W48-S	Yellow	20A, 250V, 2P, 3W, Locking Single Outlet	
66W48	Yellow	20A, 250V, 2P, 3W, Locking Single Inlet	
76W48-C	Yellow	20A, 250V, 2P, 3W, Locking Connector for Single Inlet	
26W49	Yellow	20A, 277V, 2P, 3W, Locking Plug	IP69K
27W49	Yellow	20A, 277V, 2P, 3W, Locking Connector	
97W49-S	Yellow	20A, 277V, 2P, 3W, Locking Single Outlet	
66W49	Yellow	20A, 277V, 2P, 3W, Locking Single Inlet	
76W49-C	Yellow	20A, 277V, 2P, 3W, Locking Connector for Single Inlet	

\* Replacement interior available. To order, add "-IN" to catalog number (Ex: 27W47-IN).

‡ Wetguard plugs & connectors are IP69K rated when caps are attached (Listed on page 7).

# WETGUARD® WATERTIGHT WIRING DEVICES

CAT #	COLOR	DESCRIPTION	
<b>20 Amp Locking Devices</b>			
22W07	Yellow	20A, 347V, 2P, 3W, Locking Plug	IP69K
23W07	Yellow	20A, 347V, 2P, 3W, Locking Connector	
93W07-S	Yellow	20A, 347V, 2P, 3W, Locking Single Outlet	
68W29	Yellow	20A, 347V, 2P, 3W, Locking Single Inlet	
78W29-C	Yellow	20A, 347V, 2P, 3W, Locking Connector for Single Inlet	IP69K
26W08	Yellow	20A, 125/250V, 3P, 3W, Locking Plug	
27W08	Yellow	20A, 125/250V, 3P, 3W, Locking Connector	
97W08-S	Yellow	20A, 125/250V, 3P, 3W, Locking Single Outlet	
66W08	Yellow	20A, 125/250V, 3P, 3W, Locking Single Inlet	IP69K
76W08-C	Yellow	20A, 125/250V, 3P, 3W, Locking Connector for Single Inlet	
26W08-G	Yellow	20A, 250V, 3P, 3W, Locking Plug	
27W08-G	Yellow	20A, 250V, 3P, 3W, Locking Connector	
26W74*	Yellow	20A, 125/250V, 3P, 4W, Locking Plug	IP69K
26W74-B	Black	20A, 125/250V, 3P, 4W, Locking Plug	
27W74*	Yellow	20A, 125/250V, 3P, 4W, Locking Connector	
27W74-B	Black	20A, 125/250V, 3P, 4W, Locking Connector	
97W74-S	Yellow	20A, 125/250V, 3P, 4W, Locking Single Outlet	IP69K
66W74	Yellow	20A, 125/250V, 3P, 4W, Locking Single Inlet	
76W74-C	Yellow	20A, 125/250V, 3P, 4W, Locking Connector for Single Inlet	
26W75	Yellow	20A, 3-Phase 250V, 3P, 4W, Locking Plug	
26W75-B	Black	20A, 3-Phase 250V, 3P, 4W, Locking Plug	IP69K
27W75	Yellow	20A, 3-Phase 250V, 3P, 4W, Locking Connector	
27W75-B	Black	20A, 3-Phase 250V, 3P, 4W, Locking Connector	
97W75-S	Yellow	20A, 3-Phase 250V, 3P, 4W, Locking Single Outlet	
66W75	Yellow	20A, 3-Phase 250V, 3P, 4W, Locking Single Inlet	IP69K
76W75-C	Yellow	20A, 3-Phase 250V, 3P, 4W, Locking Connector for Single Inlet	
26W76*	Yellow	20A, 3-Phase 480V, 3P, 4W, Locking Plug	
26W76-B	Black	20A, 3-Phase 480V, 3P, 4W, Locking Plug	
27W76*	Yellow	20A, 3-Phase 480V, 3P, 4W, Locking Connector	IP69K
27W76-B	Black	20A, 3-Phase 480V, 3P, 4W, Locking Connector	
97W76-S	Yellow	20A, 3-Phase 480V, 3P, 4W, Locking Single Outlet	
66W76	Yellow	20A, 3-Phase 480V, 3P, 4W, Locking Single Inlet	
76W76-C	Yellow	20A, 3-Phase 480V, 3P, 4W, Locking Connector for Single Inlet	IP69K
26W09	Yellow	20A, 3-Phase 120/208V, 4P, 4W, Locking Plug	
27W09	Yellow	20A, 3-Phase 120/208V, 4P, 4W, Locking Connector	
97W09-S	Yellow	20A, 3-Phase 120/208V, 4P, 4W, Locking Single Outlet	
66W09	Yellow	20A, 3-Phase 120/208V, 4P, 4W, Locking Single Inlet	IP69K
76W09-C	Yellow	20A, 3-Phase 120/208V, 4P, 4W, Locking Connector for Single Inlet	
26W81	Yellow	20A, 3-Phase 120/208V, 4P, 5W, Locking Plug	
26W81-B	Black	20A, 3-Phase 120/208V, 4P, 5W, Locking Plug	
27W81	Yellow	20A, 3-Phase 120/208V, 4P, 5W, Locking Connector	IP69K
27W81-B	Black	20A, 3-Phase 120/208V, 4P, 5W, Locking Connector	
97W81-S	Yellow	20A, 3-Phase 120/208V, 4P, 5W, Locking Single Outlet	
66W81	Yellow	20A, 3-Phase 120/208V, 4P, 5W, Locking Single Inlet	
76W81-C	Yellow	20A, 3-Phase 120/208V, 4P, 5W, Locking Connector for Single Inlet	IP69K
26W82	Yellow	20A, 3-Phase 277/480V, 4P, 5W, Locking Plug	
27W82	Yellow	20A, 3-Phase 277/480V, 4P, 5W, Locking Connector	
97W28-S	Yellow	20A, 3-Phase 277/480V, 4P, 5W, Locking Single Outlet	
66W82	Yellow	20A, 3-Phase 277/480V, 4P, 5W, Locking Single Inlet	IP69K
76W82-C	Yellow	20A, 3-Phase 277/480V, 4P, 5W, Locking Connector for Single Inlet	



76W09-C



99W76-SB



FDBX1-Y



28W48-B



27W74-IN

\* Replacement interior available. To order, add "-IN" to catalog number (Ex: 26W74-IN).

‡ Wetguard plugs & connectors are IP69K rated when caps are attached (Listed on page 7).





26W83



87W07-D



76W76-C



99W76-S



14W47

CAT #	COLOR	DESCRIPTION	
<b>20 Amp Locking Devices</b>			
26W83	Yellow	20A, 3-Phase 347/600V, 4P, 5W, Locking Plug	IP69K ‡
27W83	Yellow	20A, 3-Phase 347/600V, 4P, 5W, Locking Connector	
97W83-S	Yellow	20A, 3-Phase 347/600V, 4P, 5W, Locking Single Outlet	
66W83	Yellow	20A, 3-Phase 347/600V, 4P, 5W, Locking Single Inlet	
76W83-C	Yellow	20A, 3-Phase 347/600V, 4P, 5W, Locking Connector for Single Inlet	
26W10	Yellow	20A, 250V, 4P, 5W, Locking Plug	IP69K ‡
27W10	Yellow	20A, 250V, 4P, 5W, Locking Connector	
97W10-S	Yellow	20A, 250V, 4P, 5W, Locking Single Outlet	
66W10	Yellow	20A, 250V, 4P, 5W, Locking Single Inlet	
76W10-C	Yellow	20A, 250V, 4P, 5W, Locking Connector for Single Inlet	
<b>30 Amp Locking Devices</b>			
28W47	Yellow	30A, 125V, 2P, 3W, Locking Plug	IP69K ‡
28W47-B	Black	30A, 125V, 2P, 3W, Locking Plug	
29W47	Yellow	30A, 125V, 2P, 3W, Locking Connector	
29W47-B	Black	30A, 125V, 2P, 3W, Locking Connector	
99W47-S	Yellow	30A, 125V, 2P, 3W, Locking Single Outlet	
68W47	Yellow	30A, 125V, 2P, 3W, Locking Single Inlet	
78W47-C	Yellow	30A, 125V, 2P, 3W, Locking Connector for Single Inlet	
28W48	Yellow	30A, 250V, 2P, 3W, Locking Plug	IP69K ‡
29W48	Yellow	30A, 250V, 2P, 3W, Locking Connector	
99W48-S	Yellow	30A, 250V, 2P, 3W, Locking Single Outlet	
68W48	Yellow	30A, 250V, 2P, 3W, Locking Single Inlet	
78W48-C	Yellow	30A, 250V, 2P, 3W, Locking Connector for Single Inlet	
28W49	Yellow	30A, 277V, 2P, 3W, Locking Plug	IP69K ‡
29W49	Yellow	30A, 277V, 2P, 3W, Locking Connector	
99W49-S	Yellow	30A, 277V, 2P, 3W, Locking Single Outlet	
68W49	Yellow	30A, 277V, 2P, 3W, Locking Single Inlet	
78W49-C	Yellow	30A, 277V, 2P, 3W, Locking Connector for Single Inlet	
28W08	Yellow	30A, 125/250V, 3P, 3W, Locking Plug	IP69K ‡
29W08	Yellow	30A, 125/250V, 3P, 3W, Locking Connector	
99W08-S	Yellow	30A, 125/250V, 3P, 3W, Locking Single Outlet	
68W08	Yellow	30A, 125/250V, 3P, 3W, Locking Single Inlet	
78W08-C	Yellow	30A, 125/250V, 3P, 3W, Locking Connector for Single Inlet	
28W74*	Yellow	30A, 125/250V, 3P, 4W, Locking Plug	IP69K ‡
29W74*	Yellow	30A, 125/250V, 3P, 4W, Locking Connector	
99W74-S	Yellow	30A, 125/250V, 3P, 4W, Locking Single Outlet	
68W74	Yellow	30A, 125/250V, 3P, 4W, Locking Single Inlet	
78W74-C	Yellow	30A, 125/250V, 3P, 4W, Locking Connector for Single Inlet	

\* Replacement interior available. To order, add "-IN" to catalog number (Ex: 29W74-IN).

‡ Wetguard plugs & connectors are IP69K rated when caps are attached (Listed on page 7).

# WETGUARD® WATERTIGHT WIRING DEVICES

CAT #	COLOR	DESCRIPTION	
<b>30 Amp Locking Devices</b>			
28W75*	Yellow	30A, 3-Phase 250V, 3P, 4W, Locking Plug	IP69K
28W75-B	Black	30A, 3-Phase 250V, 3P, 4W, Locking Plug	
29W75*	Yellow	30A, 3-Phase 250V, 3P, 4W, Locking Connector	
29W75-B	Black	30A, 3-Phase 250V, 3P, 4W, Locking Connector	
99W75-S	Yellow	30A, 3-Phase 250V, 3P, 4W, Locking Single Outlet	
68W75	Yellow	30A, 3-Phase 250V, 3P, 4W, Locking Single Inlet	
78W75-C	Yellow	30A, 3-Phase 250V, 3P, 4W, Locking Connector for Single Inlet	
28W76*	Yellow	30A, 3-Phase 480V, 3P, 4W, Locking Plug	IP69K
29W76*	Yellow	30A, 3-Phase 480V, 3P, 4W, Locking Connector	
99W76-S	Yellow	30A, 3-Phase 480V, 3P, 4W, Locking Single Outlet	
68W76	Yellow	30A, 3-Phase 480V, 3P, 4W, Locking Single Inlet	
78W76-C	Yellow	30A, 3-Phase 480V, 3P, 4W, Locking Connector for Single Inlet	
28W77	Yellow	30A, 3-Phase Y 600V, 3P, 4W, Locking Plug	IP69K
28W77-B	Black	30A, 3-Phase Y 600V, 3P, 4W, Locking Plug	
29W77	Yellow	30A, 3-Phase Y 600V, 3P, 4W, Locking Connector	
29W77-B	Black	30A, 3-Phase Y 600V, 3P, 4W, Locking Connector	
99W77-S	Yellow	30A, 3-Phase Y 600V, 3P, 4W, Locking Single Outlet	
68W77	Yellow	30A, 3-Phase Y 600V, 3P, 4W, Locking Single Inlet	
78W77-C	Yellow	30A, 3-Phase Y 600V, 3P, 4W, Locking Connector for Single Inlet	
28W09	Yellow	30A, 3-Phase Y 120/208V, 4P, 4W, Locking Plug	IP69K
29W09	Yellow	30A, 3-Phase Y 120/208V, 4P, 4W, Locking Connector	
99W09-S	Yellow	30A, 3-Phase Y 120/208V, 4P, 4W, Locking Single Outlet	
68W09	Yellow	30A, 3-Phase Y 120/208V, 4P, 4W, Locking Single Inlet	
78W09-C	Yellow	30A, 3-Phase Y 120/208V, 4P, 4W, Locking Connector for Single Inlet	
28W81	Yellow	30A, 3-Phase Y 120/208V, 4P, 5W, Locking Plug	IP69K
29W81	Yellow	30A, 3-Phase Y 120/208V, 4P, 5W, Locking Connector	
99W81-S	Yellow	30A, 3-Phase Y 120/208V, 4P, 5W, Locking Single Outlet	
68W81	Yellow	30A, 3-Phase Y 120/208V, 4P, 5W, Locking Single Inlet	
78W81-C	Yellow	30A, 3-Phase Y 120/208V, 4P, 5W, Locking Connector for Single Inlet	
28W82	Yellow	30A, 3-Phase Y 277/480V, 4P, 5W, Locking Plug	IP69K
29W82	Yellow	30A, 3-Phase Y 277/480V, 4P, 5W, Locking Connector	
99W82-S	Yellow	30A, 3-Phase Y 277/480V, 4P, 5W, Locking Single Outlet	
68W82	Yellow	30A, 3-Phase Y 277/480V, 4P, 5W, Locking Single Inlet	
78W82-C	Yellow	30A, 3-Phase Y 277/480V, 4P, 5W, Locking Connector for Single Inlet	
28W83	Yellow	30A, 3-Phase Y 347/600V, 4P, 5W, Locking Plug	IP69K
29W83	Yellow	30A, 3-Phase Y 347/600V, 4P, 5W, Locking Connector	
99W83-S	Yellow	30A, 3-Phase Y 347/600V, 4P, 5W, Locking Single Outlet	
68W83	Yellow	30A, 3-Phase Y 347/600V, 4P, 5W, Locking Single Inlet	
78W83-C	Yellow	30A, 3-Phase Y 347/600V, 4P, 5W, Locking Connector for Single Inlet	



26W47



FDSS2



76W47-C



FDBX3-GY

\* Replacement interior available. To order, add "-IN" to catalog number (Ex: 29W75-IN).

‡ Wetguard plugs & connectors are IP69K rated when caps are attached (Listed below).

Wetguard Plugs & Connectors Are IP69K Rated When Caps Are Attached	IP69K		
	Closure Caps	Connector Caps	Plug Caps
	15/20 A Straight Blade and 15 A Locking	50W50	14W
	20 A Locking	50W52	26W
30 A Locking	50W54	28W	



COVER-S

## Value Proposition:

A complete collection of watertight devices to help protect electrical connections from water, moisture and dust that can damage equipment and operations.

## Sales Tips:

- **Industry leading warranty**
  - Unmatched limited lifetime warranty!
- **Superior environmental protection in wet and corrosive environments**
  - Plugs and connectors are IP69K rated when caps are attached
  - Plug body mates with outer husk in a “tongue and groove” design that provides an impenetrable barrier against dirt and moisture
  - Corrosion-resistant electroless nickel-coated brass blades, contacts, terminal screws and wiring clamps, and stainless steel assembly screws
- **Innovative strain relief on plugs & connectors**
  - Separate, three-piece adjustable strain relief is superior to competitor’s designs
  - Compression nut system maintains integrity of electrical connection and watertight seal
- **Durable material**
  - Santoprene™ thermoplastic (TPV) provides unparalleled durability and resistance to water and chemicals compared to rubber
  - Withstands prolonged UV exposure for the harshest environments

## Customer Needs:

- **Customers working in wet and damp environments:**
  - Is water seepage destroying plugs and connectors that ultimately need to be replaced?
  - Is corrosion an issue in your facility?

## Customer Benefits:

- **Wetguard devices offer a complete watertight electrical solution for indoor facilities with washdown requirements, or outdoor areas exposed to natural elements.**
  - Food & beverage processing – maximize uptime of equipment and safety to workers
  - Chemical processing/Water treatment – materials will resist corrosion and damaging chemical exposure
  - Construction – withstands the rigors of harsh weather conditions

## Assets:

Available at [www.leviton.com/wetguard](http://www.leviton.com/wetguard):

- Brochure
- Cross-Reference
- Overview Video
- Installation Video
- Installation Instructions
- Dimensional Drawings
- Specification Tables

Contact [industrial@leviton.com](mailto:industrial@leviton.com) for the following:

- Custom E-blasts
- Product Training PowerPoint Presentation
- Digital Enhancements
  - Keywords for search optimization
  - Hi-Res imagery
  - Detailed product descriptions and specifications

Visit our Website at:

[leviton.com/wetguard](http://leviton.com/wetguard)

email: [industrial@leviton.com](mailto:industrial@leviton.com)

Q-1091B

020820

Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747

Telephone: 1-800-323-8920 • FAX: 1-800-832-9538

Tech Line: 1-800-824-3005 (M-F 8AM-10PM; Sat 9AM-7PM; Sun 9AM-5PM)

© 2020 Leviton Manufacturing Co., Inc. All rights reserved.

